



BDBLCS7R3DW, Large Flex Rated Power Distribution Block

By Burndy
Catalog # [BDBLCS7R3DW](#)

Double Wide Power Distribution Block, 3 Pole, Run: #4 AWG - 500 (B,C,H,I,K, 535 DLO), Tap: #6-4/0 AWG (B,C,H,I,K, DLO)

Features


- AL9CU dual rated for use with copper and aluminum conductors
- Range taking designs accommodate wire sizes up to 535 DLO and can support 1 or 2 run conductors and up to 12 taps for secondary circuits
- Allow for panel mounting, medium and large sizes also allow for DIN rail mounting
- Finger-Safe style are provided with translucent polycarbonate top covers and end plates permitting easy visual inspection, provide IEC 605219 IP-20 Rating
- Base and side barriers of glass-reinforced nylon 6/6 for extra durability and excellent insulating properties
- UL94 flammability rating of VO
- Double-Wide Series

Specifications

Certification - CSA Approved	No
Certification - cULus	Yes
Certification - UL Recognized	No

[Catalog \[English\]](#)

Image represents single pole

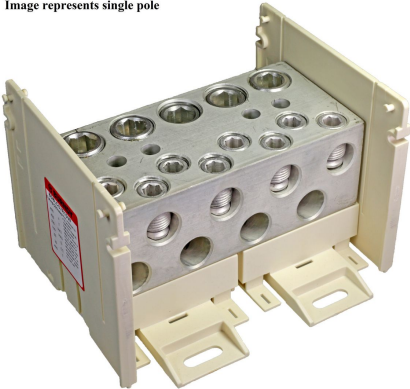

Standards - RoHS Compliance CM
Status

Configuration

Connector Type Power Distribution Block

Dimensions

Weight 8.52 lb.

General

Material Aluminum
UPC 621945518551
Trade Name VERSIPOLE™

Logistics

Minimum Pack Quantity 1
Carton Quantity 1
Pallet Quantity 84

Product Assets