




**BIBD2/08MT, 2-Sided, Mount, 8-Cond.
Clear Ins. MultiTap**

By Burndy
Catalog # [BIBD2/08MT](#)

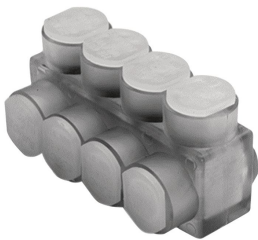

#14 - 2/0 AWG, 8 Ports, Double-sided Entry, Al/Cu Rated,
Mountable, Clear Plastisol allows visual confirmation conductor is
properly inserted

Features

- Clear Plastisol covered AL6061-T6 aluminum body saves times and lowers installation costs and eliminates taping
- Clear plastisol allows visual confirmation that conductor is properly inserted
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - AL Str Size	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor - AL Str Size Range	8 AWG-2/0 AWG
Conductor - Copper Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG

Conductor Size	• 1 AWG • 1/0 • 2/0 AWG
Conductor Type	14-2/0 AWG • AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	14 AWG - 2/0 AWG

Configuration

Physical Attribute - Number of Screws	10
Number Of Ports	8
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	38.1 mm
Dimension - Height inch	1.50 in
Dimension - Height fraction	1.5 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	175 mm
Dimension - Width fraction	1-14/25 in
Dimension - Width mm	40 mm
Dimension - Width inch	1.56 in
Dimension - Length Overall inch	6.89 in

General

Insulation Type	Plastisol
Trade Name	UNITAP™
Material - Hardware	Aluminum
Insulation	Y
Physical Attribute - Screw Type	Allen
Plated	N
UPC	781810253243
Hex Key	3/16
Material	Aluminum
Plating Type	Unplated

UPC 12 Digit781810253243

UPC 14 Digit GTIN00781810253243

Operational

Temperature Rating194

Logistics

Minimum Pack Quantity5

Pallet Quantity2700

Carton Quantity100

Product Assets

[Catalog \[English\]](#)

[Catalog \[English\]](#)

