



# BIBD7506HD, Double Sided Heavy Duty Clear Insulated Six Conductor Mult-Tap Connector

By Burndy  
Catalog # [BIBD7506HD](#)

Mounting Version Multi-Port Double-Sided Entry

## Features

- Plastisol covered AL 6060-T6 Body
- Saves time and lowers installation cost
- Eliminates taping
- Oxide inhibitor is prefilled
- Inhibits moisture and contaminants from entering the contact area
- Wire and Screw Port Covers protects against contamination and accidental contact of energized parts

## Application

For Indoor Use Only, Copper Or Stranded Aluminum

## Specifications


|                              |     |
|------------------------------|-----|
| Certification - ETL          | No  |
| Standards - RoHS Compliance  | CM  |
| Status                       |     |
| Certification - CSA Approved | Yes |
| UL Listed                    | Yes |

## Conductor

|                |                                |
|----------------|--------------------------------|
| Wire Size      | #2 AWG TO 750 kcmil Class B, C |
| Conductor Size | 2 AWG-750 KCMIL                |

## Configuration

|                 |           |
|-----------------|-----------|
| Connector Type  | Multi Tap |
| Number Of Ports | 6         |

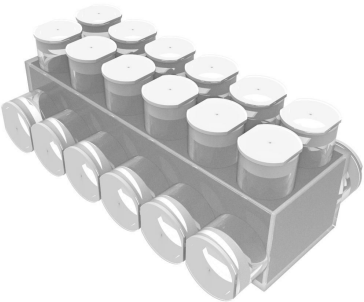

## Current

|                   |       |
|-------------------|-------|
| Amperage Rating   | 535 A |
| Voltage - Maximum | 600 V |
| Voltage Rating    | 600 V |

## Dimensions

|        |         |
|--------|---------|
| Length | 8.13 in |
| Width  | 4.83 in |

## General

|                       |                       |
|-----------------------|-----------------------|
| Material Type - Screw | Clear Coated Aluminum |
| Material - Body       | Tin Plated Aluminum   |
| Material              | Aluminum              |
| Hex Key               | 3/8 in                |
| Material - Insulation | Plastisol             |
| UPC                   | 621945480865          |

## Logistics

|                       |     |
|-----------------------|-----|
| Minimum Pack Quantity | 1   |
| Carton Quantity       | 6   |
| Pallet Quantity       | 192 |

## Operational

|                       |                 |
|-----------------------|-----------------|
| Operating Temperature | -40°C TO 135°C. |
|-----------------------|-----------------|

## Product Assets

[Catalog \[English\]](#)