



BIBD7508HD, Double Sided Heavy Duty Clear Insulated Eight Conductor Multi-Tap Connector

By Burndy
Catalog # [BIBD7508HD](#)

Mounting Version Multi-Port Double-Sided Entry

Features

- Plastisol covered AL 6060-T6 Body
- Saves time and lowers installation cost
- Eliminates taping
- Oxide inhibitor is prefilled
- Inhibits moisture and contaminants from entering the contact area
- Wire and Screw Port Covers protects against contamination and accidental contact of energized parts

Application

For Indoor Use Only, Copper Or Stranded Aluminum

Specifications


Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	Yes
UL Listed	Yes

Conductor

Wire Size	#2 AWG TO 750 kcmil Class B, C
Conductor Size	2 AWG-750 KCMIL

Configuration

Connector Type	Multi Tap
Number Of Ports	8

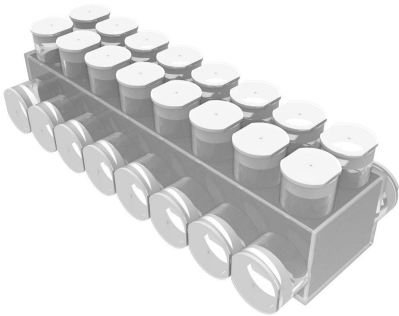

Current

Amperage Rating	535 A
Voltage - Maximum	600 V
Voltage Rating	600 V

Dimensions

Length	10.88 in
Width	4.83 in

General

Material Type - Screw	Clear Coated Aluminum
Material - Body	Tin Plated Aluminum
Material	Aluminum
Hex Key	3/8 in
Material - Insulation	Plastisol
UPC	621945480872

Logistics

Minimum Pack Quantity	1
Carton Quantity	1
Pallet Quantity	1

Operational

Operating Temperature	-40°C TO 135°C.
-----------------------	-----------------

Product Assets

[Catalog \[English\]](#)