




BIBS2/010MT, Mount, 10-Cond. Clear Ins. MultiTap

By Burndy
Catalog # [BIBS2/010MT](#)

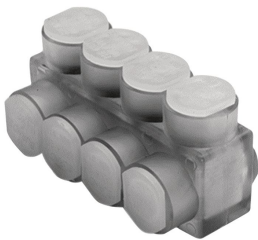

#14 - 2/0 AWG, 10 Ports, Single-sided Entry, Al/Cu Rated, Mountable, Clear Plastisol allows visual confirmation conductor is properly inserted

Features

- Clear Plastisol covered AL6061-T6 aluminum body saves times and lowers installation costs and eliminates taping
- Clear plastisol allows visual confirmation that conductor is properly inserted
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	14-2/0 AWG
Conductor - AL Str Size	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor - AL Str Size Range	8 AWG-2/0 AWG
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	14 AWG - 2/0 AWG
Conductor - Copper Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG

- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 Str

Configuration

Physical Attribute - Number of Screws	12
Number Of Ports	10
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	38.1 mm
Length	8.23 in
Dimension - Height inch	1.50 in
Dimension - Height fraction	1.5 in
Package Weight	0.000 lb.
Dimension - Width mm	32 mm
Dimension - Width inch	1.25 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	209 mm
Height	1.5 in
Width	1.25 in
Dimension - Width fraction	1-31/100 in
Dimension - Length Overall inch	8.23 in
Dimensions	8.23 in x 1.25 in x 1.5 in

General

Physical Attribute - Screw Type	Allen
Plated	N
Insulation Type	Plastisol
Trade Name	UNITAP™
Material - Hardware	Aluminum
UPC	781810252895

Insulation	Y
Hex Key	3/16
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810252895
UPC 14 Digit GTIN	00781810252895

Logistics



A Hubbell brand

Minimum Pack Quantity	5
-----------------------	---

Operational

Temperature Rating	194
--------------------	-----

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)