


BIBS2/08MT, Mount, 8-Cond. Clear Ins. MultiTap

By Burndy

Catalog # [BIBS2/08MT](#)

#14 - 2/0 AWG, 8 Ports, Single-sided Entry, Al/Cu Rated, Mountable, Clear Plastisol allows visual confirmation conductor is properly inserted

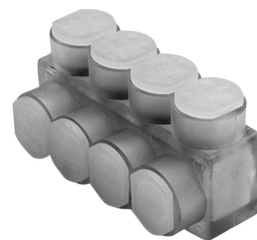

Features

- Clear Plastisol covered AL6061-T6 aluminum body saves times and lowers installation costs and eliminates taping
- Clear plastisol allows visual confirmation that conductor is properly inserted
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces number of connectors necessary to carry in inventory

Specifications

Standards - Industry Standards Met	UL467
Certification - UL Listed Direct Burial	No
Industry Standard(s)	UL467
Certification - CSA Approved	Yes

Conductor

Conductor Size	14-2/0 AWG
Conductor - AL Str Size Range	14 AWG - 2/0 AWG
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	14 AWG - 2/0 AWG

Configuration

Physical Attribute - Number of Screws	10
Number Of Ports	8
Connector Type	Multi Tap

Current

Operating Voltage	600 V
Voltage - Maximum	600 V

Dimensions

Dimension - Height mm	35 mm
Length	6.89 in
Dimension - Height inch	1.50 in
Dimension - Width mm	32 mm
Dimension - Width inch	1.25 in
Dimension - L Length Overall mm	175 mm
Height	1.5 in
Width	1.25 in
Dimension - Width fraction	1-31/100 in
Dimension - Length Overall inch	6.89 in
Dimensions	6.89 in x 1.25 in x 1.5 in

General

Physical Attribute - Screw Type	Allen
Plated	N
Insulation Type	Plastisol
Trade Name	UNITAP™
UPC	781810252888
Insulation	Y
Hex Key	3/16
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810252888
UPC 14 Digit GTIN	00781810252888

Logistics

Minimum Pack Quantity	1
-----------------------	---

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)