




# BIBS2508MT, Mount, 8-Cond. Clear Ins. MultiTap

By Burndy  
Catalog # [BIBS2508MT](#)

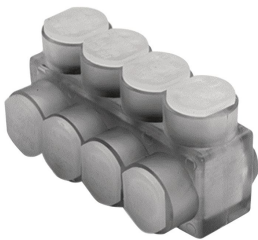

#10 AWG - 250 kcmil, 8 Ports, Single-sided Entry, Al/Cu Rated, Mountable, Clear Plastisol allows visual confirmation conductor is properly inserted

## Features

- Clear Plastisol covered AL6061-T6 aluminum body saves times and lowers installation costs and eliminates taping
- Clear plastisol allows visual confirmation that conductor is properly inserted
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces number of connectors necessary to carry in inventory

## Specifications

|                                         |       |
|-----------------------------------------|-------|
| Certification - ETL                     | No    |
| Certification - UL Recognized           | No    |
| Standards - Industry Standards Met      | UL467 |
| Standards - RoHS Compliance Status      | CM    |
| Certification - cULus                   | No    |
| Certification - UL Listed Direct Burial | No    |
| Industry Standard(s)                    | UL467 |
| UL Listed                               | Yes   |
| Certification - CSA Approved            | Yes   |

## Conductor

|                                   |                                                                                         |
|-----------------------------------|-----------------------------------------------------------------------------------------|
| Conductor Size                    | 10 AWG-250 KCMIL                                                                        |
| Conductor - AL Str Size Range     | 10 AWG - 250 kcmil                                                                      |
| Conductor Type                    | <ul style="list-style-type: none"><li>• AL C Str-Size</li><li>• CU C Str-Size</li></ul> |
| Conductor - Copper Str Size Range | 10 AWG - 250 kcmil                                                                      |

## Configuration

|                                       |           |
|---------------------------------------|-----------|
| Physical Attribute - Number of Screws | 10        |
| Number Of Ports                       | 8         |
| Connector Type                        | Multi Tap |

## Current

|                   |       |
|-------------------|-------|
| Voltage - Maximum | 600 V |
|-------------------|-------|

## Dimensions

|                                 |                             |
|---------------------------------|-----------------------------|
| Package Height                  | 0.000 in                    |
| Dimension - Height mm           | 67 mm                       |
| Length                          | 9.53 in                     |
| Dimension - Height inch         | 2.63 in                     |
| Package Weight                  | 0.000 lb.                   |
| Dimension - Width mm            | 50 mm                       |
| Dimension - Width inch          | 1.95 in                     |
| Package Length                  | 0.000 in                    |
| Package Width                   | 0.000 in                    |
| Dimension - L Length Overall mm | 242 mm                      |
| Height                          | 2.63 in                     |
| Width                           | 1.95 in                     |
| Dimension - Length Overall inch | 9.53 in                     |
| Dimensions                      | 9.53 in x 1.95 in x 2.63 in |

## General

|                                 |                |
|---------------------------------|----------------|
| Physical Attribute - Screw Type | Allen          |
| Plated                          | N              |
| Insulation Type                 | Plastisol      |
| Trade Name                      | UNITAP™        |
| UPC                             | 781810252949   |
| Insulation                      | Y              |
| Hex Key                         | 5/16           |
| Material                        | Aluminum       |
| Plating Type                    | Unplated       |
| UPC 12 Digit                    | 781810252949   |
| UPC 14 Digit GTIN               | 00781810252949 |

## Logistics

|                       |      |
|-----------------------|------|
| Minimum Pack Quantity | 5    |
| Pallet Quantity       | 1458 |
| Carton Quantity       | 54   |

## Operational

|                    |     |
|--------------------|-----|
| Temperature Rating | 194 |
|--------------------|-----|

## Product Assets

[Catalog \[English\]](#)  
[Catalog \[English\]](#)