


BIBS6004MT, Mount, 4-Cond. Clear Ins. MultiTap

By Burndy

Catalog # [BIBS6004MT](#)

Aluminum UNITAP, Mountable, Single Sided Entry, 4 Port, #4 AWG-600 kcmil, Al/Cu Rated

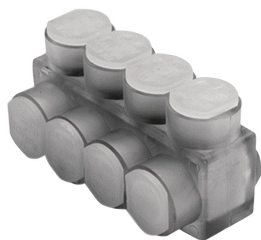

Features

- Clear Plastisol covered AL6061-T6 aluminum body saves times and lowers installation costs and eliminates taping
- Clear plastisol allows visual confirmation that conductor is properly inserted
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor Size	4 AWG-600 KCMIL
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	4 AWG - 600 kcmil

Configuration

Physical Attribute - Number of Screws	6
Number Of Ports	4
Connector Type	Multi Tap

Current

Operating Voltage	600 V
Voltage - Maximum	600 V

Dimensions

Package Height	0.000 in
Dimension - Height mm	73 mm
Dimension - Height inch	2.88 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	199 mm
Width	2.25 in
Length	7.84 in
Dimension - Width mm	57 mm
Dimension - Width inch	2.25 in
Height	2.88 in
Dimension - Length Overall inch	7.84 in
Dimensions	7.84 in x 2.25 in x 2.88 in

General

Insulation Type	Plastisol
Trade Name	UNITAP™
Insulation	Y
Physical Attribute - Screw Type	Allen
Plated	N
UPC	781810253168
Hex Key	3/8
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810253168
UPC 14 Digit GTIN	00781810253168

Logistics

Minimum Pack Quantity	5
Pallet Quantity	540
Carton Quantity	20

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)