


## BIT4, 1-Side, 2-Cond. Clear Ins., MultiTap

By Burndy  
Catalog # [BIT4](#)

Aluminum Multiple Tap Connector, Clear Insulated, 2 Port, 1 Sided Entry,  
14-4 AWG, Al/Cu Rated

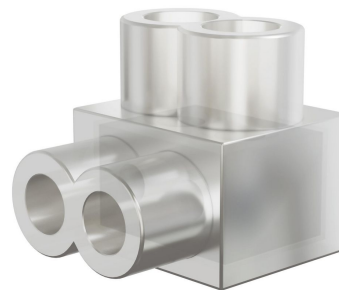

### Features

- Type BIT and BITO (Offset) Multi-tap connectors are installed quickly and easily
- Suitable for use on Code conductor
- UL486B Listed, Dual-rated AL9CU.

### Application

For Indoor Use Only, Copper Or Stranded Aluminum

### Specifications

|                                         |                                                      |
|-----------------------------------------|------------------------------------------------------|
| Buy American Compliant                  | Contact Manufacturer                                 |
| Buy America(n) Qualified                | BABA Compliant (All status valid till December 2026) |
| Industry Standard(s)                    | UL 486A-486B                                         |
| Standards - Industry Standards Met      | UL 486A-486B                                         |
| Standards - RoHS Compliance             | CM                                                   |
| Status                                  |                                                      |
| Certification - UL Listed Direct Burial | No                                                   |
| UL Listed                               | Yes                                                  |
| Certification - CSA Approved            | Yes                                                  |

### Conductor

|                                   |                                                                                                                                                                                            |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Conductor - AL Str Size           | <ul style="list-style-type: none"><li>• 8 AWG</li><li>• 6 AWG</li><li>• 4 AWG</li></ul>                                                                                                    |
| Conductor - AL Str Size Range     | 14 AWG - 4 AWG                                                                                                                                                                             |
| Conductor - Copper Str Size       | <ul style="list-style-type: none"><li>• 14 AWG</li><li>• 12 AWG</li><li>• 10 AWG</li><li>• 9 AWG</li><li>• 8 AWG</li><li>• 7 AWG</li><li>• 6 AWG</li><li>• 5 AWG</li><li>• 4 AWG</li></ul> |
| Conductor Size                    | 14-4 AWG                                                                                                                                                                                   |
| Conductor Type                    | <ul style="list-style-type: none"><li>• AL C Str-Size</li><li>• CU C Str-Size</li></ul>                                                                                                    |
| Conductor - Copper Str Size Range | 14 AWG - 4 AWG                                                                                                                                                                             |

### Configuration

|                                       |   |
|---------------------------------------|---|
| Physical Attribute - Number of Screws | 2 |
| Number Of Ports                       | 2 |

|                |           |
|----------------|-----------|
| Connector Type | Multi Tap |
|----------------|-----------|

### Current

|                   |       |
|-------------------|-------|
| Operating Voltage | 600 V |
| Voltage - Maximum | 600 V |

### Dimensions

|                                 |           |
|---------------------------------|-----------|
| Package Height                  | 0.000 in  |
| Dimension - Height mm           | 32 mm     |
| Dimension - Height inch         | 1.25 in   |
| Package Weight                  | 0.000 lb. |
| Package Length                  | 0.000 in  |
| Package Width                   | 0.000 in  |
| Dimension - L Length Overall mm | 27 mm     |
| Dimension - Width fraction      | 1-4/25 in |
| Dimension - Width mm            | 29 mm     |
| Dimension - Width inch          | 1.16 in   |
| Dimension - Length Overall inch | 1.08 in   |

### Force Related

|                                 |          |
|---------------------------------|----------|
| Installation Torque Recommended | 45 in-lb |
|---------------------------------|----------|

### General

|                                 |                |
|---------------------------------|----------------|
| Product Family                  | MECHANICAL     |
| Insulation Type                 | Plastisol      |
| Trade Name                      | UNITAP™        |
| Material - Hardware             | Aluminum       |
| Insulation                      | Y              |
| Physical Attribute - Screw Type | Allen          |
| Plated                          | No             |
| Sub Brand                       | UNITAP         |
| Product Type                    | Run/Tap        |
| UPC                             | 781810134146   |
| Type                            | BIT            |
| Hex Key                         | 1/8 in         |
| Material                        | Aluminum       |
| Plating Type                    | Unplated       |
| UPC 12 Digit                    | 781810134146   |
| UPC 14 Digit GTIN               | 00781810134146 |

### Logistics

|                       |       |
|-----------------------|-------|
| Minimum Pack Quantity | 1     |
| Pallet Quantity       | 16000 |
| Carton Quantity       | 250   |

Operational

Temperature Rating 90 °C



A Hubbell brand

Product Assets

[Catalog \[English\]](#)

[Catalog \[English\]](#)