




BSD2050, Static Discharge Reel, Heavy Duty, Cable Length: 50'

By Burndy
Catalog # [BSD2050](#)

Static Discharge Reels, Heavy Duty, Cable Length: 50 Feet

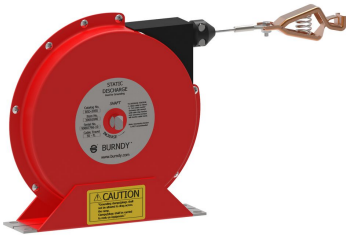

Features

- 50 foot cable length
- Automatic E-Z PULL Rewinding
- Rugged Steel Construction
- Compact Enclosed Design
- Positive Ratchet Lock with Ratchet On/Off Switch
- Steel Cable Installed
- 100 Amp Universal Jaw-Type GroundingClamp
- Red Baked-on Finish

Application

Used to dissipate static charge build-up developed while filling or dispensing fuel or other combustible liquids from fuel trucks or rail cars

Specifications

Buy American Compliant	Contact Manufacturer
Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	No

Conductor

Conductor Type	• CU C Solid-Size • CU C Str-Size
Cable Type	Aircraft Steel

Configuration

Physical Attribute - Number of Clamping Elements	1
--	---

Dimensions

Dimension - Height mm	223.5 mm
Dimension - Height inch	8.80 in

Dimension - Width mm	86 mm
Dimension - Width inch	3.40 in
Cable Length	50 ft
Cable Length Active	600
Dimension - Length Overall inch	8.60 in

Force Related

Tension	Adjustable
---------	------------

General

Plated	No
Product Family	Grounding and Bonding Connectors>Static Discharge Reels
Sub Brand	REEL
Product Type	Mechanical
Color - Housing	Red
UPC	781810504468
Type	Static Discharge Reel
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810504468
Cable Lock	Y
UPC 14 Digit GTIN	00781810504468

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)