




BULF10P, Vinyl Bullet Quick Disconnect For 12 - 10 AWG

By Burndy
Catalog # [BULF10P](#)

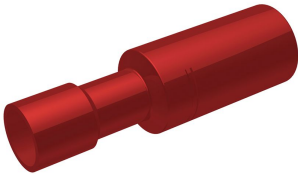

Vinyl Bullet Quick Disconnect For 12 - 10 AWG

Features

- Bullet connectors allow for quick and easy adjustments, idea for frequent maintenance without special tools
- Small size makes them perfect for tight spaces and a variety of applications from Automotive to Electronics
- Flared insulation for easier wire insertion

Application

For easier wire insertion

Specifications

Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	12 - 10 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Female Bullet Connector
----------------	-------------------------

Dimensions

Package Length	6.000 in
Package Width	4.000 in
Dimension - B Length fraction	0.20 in
Package Weight	0.160 lb.
Package Height	0.600 in
Dimension - Strip Length inch	5/16 in

General

Sub Brand	SMALL TERMINAL
Insulation Type	Vinyl
Trade Name	HYDENT™
Type	Bullet Style
UPC 12 Digit	781810523926
UPC 14 Digit GTIN	00781810523926
UPC	781810523926

Logistics

Minimum Pack Quantity	50
Carton Quantity	100
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)