


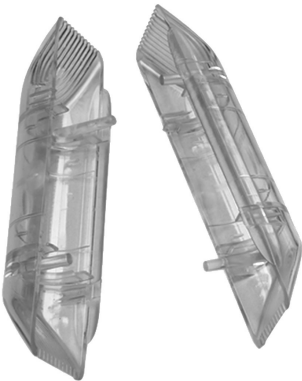

CCFBGFR, Clear Cover, Flame Retardant, #8-6 AWG H-Tap

By Burndy
Catalog # [CCFBGFR](#)

Clear Cover Only for YH8C8C or YH6C6C H-Tap Connectors, #8-6 AWG (connectors not included)



Features

- Connector end stops
- Flexible fingers
- snap tight latches
- 2piece contruction
- magnifying lens

Application

Cover

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Copper Str	8 AWG-6 AWG
Compact Size	
Conductor - Max Length	0.65 in
Conductor - Material	COPPER
Wire Size	8 AWG-6 AWG
Conductor - AL Str Size	8 AWG-6 AWG
Conductor Type	CODE/FLEX
Conductor - Copper Str Size	#8 AWG-#6 AWG
Range	
Conductor - Copper Str Size	8 AWG-6 AWG

Configuration

Connector Type	H-TAP COVERS CLEAR
----------------	--------------------

Current

Voltage Rating	600 V
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Length	3.63 in
Dimension - Height inch	1.16 in
Package Weight	0.000 lb.
Dimension - Width inch	0.85 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	92 mm
mm	
Height	1.16 in
Width	1.21 in
Dimension - Length Overall	3.63 in
inch	
Dimensions	3.63 in x 1.21 in x 1.16 in

General

Color	Clear
Plated	N
Color Code	Orange
UPC	781810438145
Material	Polycarbonate
Plating Type	Unplated
UPC 12 Digit	781810438145
UPC 14 Digit GTIN	00781810438145

Logistics

Minimum Pack Quantity	1
Pallet Quantity	3300
Carton Quantity	100

Operational

Temperature Rating	194
Operating Temperature	90 °C

Product Assets

[Catalog \[English\]](#)