


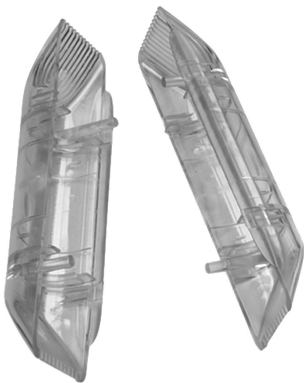

CCFDXFR, Clear Cover, Flame Retardant, for 250 kcmil H-Tap

By Burndy
Catalog # [CCFDXFR](#)

Clear Cover only for YH2929 H-Tap Connector, 250 kcmil
(connector not included)



Features

- Connector end stops
- Flexible fingers
- snap tight latches
- 2piece construction
- magnifying lens

Application

Cover

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	Yes
Certification - CSA Approved	Yes
Certification - 94V0 Rated	Y

Conductor

Conductor - Copper Str	250 KCMIL
Compact Size	
Conductor - Max Length	0.95 in
Conductor - Material	COPPER
Wire Size	250 KCMIL
Conductor - AL Str Size	250 KCMIL
Conductor Type	CODE/FLEX
Conductor - Copper Str Size	250 kcmil
Range	
Conductor - Copper Str Size	250 KCMIL

Configuration

Connector Type	H-TAP COVERS CLEAR
----------------	--------------------

Current

Voltage Rating	600 V
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Length	6 in
Dimension - Height inch	2.46 in
Package Weight	0.000 lb.
Dimension - Width inch	1.57 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	152 mm
mm	
Height	2.46 in
Width	1.57 in
Dimension - Maximum	250 kcmil
Conductor Size	
Accommodated	
Dimension - Length Overall	6 in
inch	
Dimensions	6 in x 1.57 in x 2.46 in

General

Color	Clear
Plated	N
Color Code	Purple
Sub Brand	FLAME RETARDENT COVER
UPC	781810452141
Type	CCF-FR,Flame Retardant
Material	POLYCARBONATE
Plating Type	Unplated
UPC 12 Digit	781810452141
Fire Resistance	Yes
UPC 14 Digit GTIN	00781810452141

Logistics

Pallet Quantity	450
Carton Quantity	5

Operational

Temperature Rating	194
Operating Temperature	90 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand