


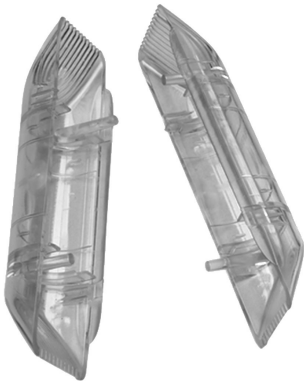

CCFNFR, Clear Cover, Flame Retardant, for 500 kcmil H-Tap

By Burndy
Catalog # [CCFNFR](#)

Clear Cover only for YH3434, YH3429 H-Tap Connectors, 500 kcmil (connector not included)



Features

- Connector end stops
- Flexible fingers
- snap tight latches
- 2piece contruction
- magnifying lens

Application

Cover

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	Yes
Certification - CSA Approved	Yes
Certification - 94V0 Rated	Y

Conductor

Conductor - Copper Str	500 KCMIL
Compact Size	
Conductor - Max Length	1.10 in
Conductor - Material	COPPER
Wire Size	500 KCMIL
Conductor - AL Str Size	500 KCMIL
Conductor Type	CODE/FLEX
Conductor - Copper Str Size	500 kcmil
Range	
Conductor - Copper Str Size	500 KCMIL

Configuration

Connector Type	H-TAP COVERS CLEAR
----------------	--------------------

Current

Voltage Rating	600 V
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Length	7.25 in
Dimension - Height inch	2.76 in
Package Weight	0.000 lb.
Dimension - Width inch	2.05 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	184 mm
mm	
Height	2.76 in
Width	2.05 in
Dimension - Maximum	500 kcmil
Conductor Size	
Accommodated	
Dimension - Length Overall	7.25 in
inch	
Dimensions	7.25 in x 2.05 in x 2.76 in

General

Color	Clear
Plated	N
Color Code	Brown
UPC	781810438169
Material	Polycarbonate
Plating Type	Unplated
UPC 12 Digit	781810438169
Fire Resistance	Yes
UPC 14 Digit GTIN	00781810438169

Logistics

Minimum Pack Quantity	1
Pallet Quantity	900
Carton Quantity	10

Operational

Temperature Rating	194
Operating Temperature	90 °C

Product Assets

[Catalog \[English\]](#)