




BURNDY

CKS2, 1 KS23 Split Bolt packaged with Cover SC2

By Burndy

Catalog # [CKS2](#)

(1) KS23 & (1) SC2 packaged together

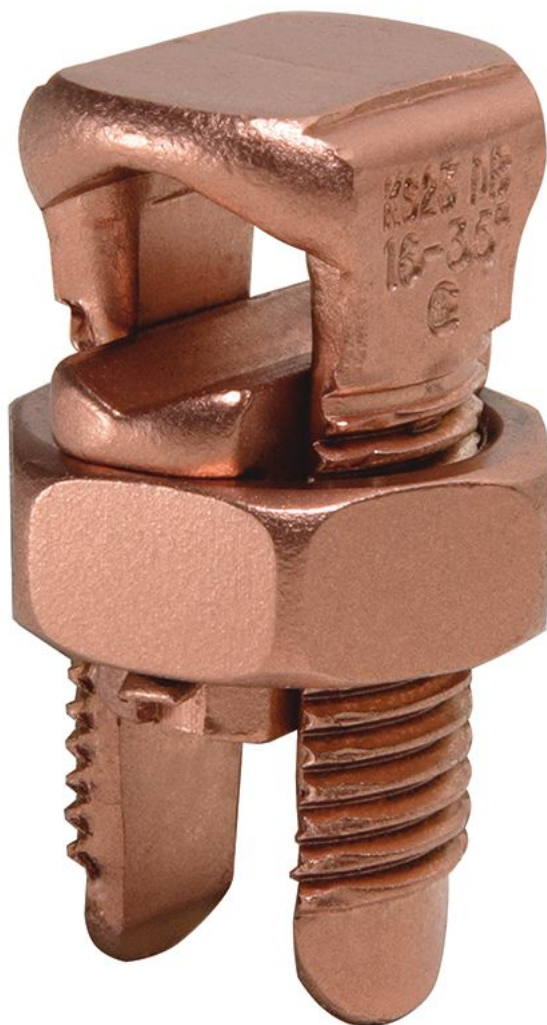

Features

- Convenience Package of KS23 Split Bolt with SC2 Cover

Specifications

Certification - ETL

No

Certification - UL Recognized

No

Standards - Industry Standards Met

- UL 486A

• UL486B
Standards - RoHS Compliance Status
CM
Certification - cULus
No
Certification - UL Listed Direct Burial
Yes
Industry Standard(s)

• UL 486A
• UL486B

UL Listed
Yes
Certification - CSA Approved
Yes

Conductor

Conductor - AAAC 5005 Tap Range
123.3 (7)-246.9 (7)
Conductor - AAAC 5005 Tap

- 123.3 (7)
- 155.4 (7)
- 195.7 (7)
- 246.9 (7)

Conductor - AAAC 5005 Run Range
155.4 (7) kcmil-312.8 (19) kcmil
Conductor - AAAC 5005 Run

- 155.4 (7)
- 195.7 (7)
- 246.9 (7)
- 312.8 (19)

Conductor Type

- CU C Solid-Run
- CU C Str-Run
- CU Weld C Solid-Run
- CU Weld C Str-Run
- CU C Str-Tap
- CU Weld C Solid-Tap
- CU Weld C Str-Tap
- CU C Solid-Tap

Configuration

Connector Type
Split Bolt

General

Plated
N
Trade Name
SERVIT®
UPC
781810288665
Material
Copper
Plating Type
Unplated
UPC 12 Digit
781810288665
UPC 14 Digit GTIN
00781810288665

Logistics

Minimum Pack Quantity
50
Pallet Quantity
7200
Carton Quantity
50

Product Assets

[Catalog.\[English\]](#)



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY-CKS2-SPEC-EN | REV 5/2026