



CKSA6, Aluminum Split Bolt and Cover Kit

By Burndy

Catalog # [CKSA6](#)

Aluminum SERVIT with Cover Kit, Packaged Together. Max Run-
Max Tap: #6 Str-#6 Str, Min Run-Min Tap: #10 Sol-#10 Sol, Max
Run -Min Tap: #6 Str-#10 Sol.

Features


- Aluminum SERVIT and Cover Kit
- Max Run to Max Tap: #6 - #6 Str
- Min Run to Min Tap: #10 - #10 Sol
- AL9CU

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
Industry Standard(s)	UL 486A-486B
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Copper Str Run Range	10 AWG-6 AWG
Conductor - Copper Str Run	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG
Conductor - Copper Solid Run Range	10 AWG-6 AWG
Conductor - Copper Solid Run	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG
Conductor - Copper Solid Tap Range	10 AWG-6 AWG
Conductor - Copper Solid Tap	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG
Conductor - AL Str Run Range	8 AWG-6 AWG
Conductor - AL Str Run	• 8 AWG • 6 AWG

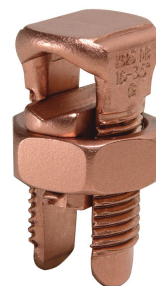

Conductor - AL Str Tap Range	8 AWG-6 AWG
Conductor - AL Str Tap	• 8 AWG • 6 AWG
Conductor - Copper Str Tap Range	10 AWG-6 AWG
Conductor - Copper Str Tap	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG

Current

Rating - Minimum Voltage	600
--------------------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	16.3 mm
Dimension - Height inch	0.64 in
Dimension - Height fraction	2/3 in
Package Weight	0.000 lb.
Dimension - Width mm	14 mm
Dimension - Width inch	0.56 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	33 mm
Dimension - Cross Flats inch	0.75 in
Dimension - Bolt Size inch	1.06 in
Dimension - Length Overall inch	1.28 in

Force Related

Installation Torque Recommended in-lb	165 LBS/in
---------------------------------------	------------

General

Plated	Y
Trade Name	TRITAP™ SERVIT®
UPC	781810051627
Material	Aluminum
Plating Type	Tin
UPC 12 Digit	781810051627
UPC 14 Digit GTIN	00781810051627

Logistics

Pallet Quantity	7200	Temperature Rating	194
Carton Quantity	50		

Operational

Product Assets

[Catalog \[English\]](#)



A Hubbell brand