



CL501, Cu Lay-in Lug, 14-4 AWG, #10 Stud, Tinned, Bulk Pkg

By Burndy
Catalog # [CL501TNBULK](#)

Copper Lay-in Lug, Accommodates #14-4 AWG Copper, #10 Stud, Tin Plated, UL467 Listed for Direct Burial, UL2703 for Solar Applications, Bulk Packed

Features

- UL2703 for Solar Applications
- UL467 for Direct Burial


Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	14 AWG - 4 AWG
Conductor - Copper Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG

Dimensions

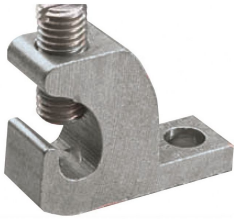

Package Height	0.000 in
Dimension - Height inch	0.85 in
Package Weight	0.000 lb.
Dimension - Width inch	0.38 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - D inch	0.47 in
Dimension - N inch	0.19 in
Dimension - Hole Size inch	0.22 in
Dimension - Length Overall inch	1.13 in
Dimension - Stud Size inch	17/64

General

Plated	Y
Trade Name	QIKLUG™
Material - Hardware	Stainless Steel
UPC	781810492796
Material	Copper
Plating Type	Tin
UPC 12 Digit	781810492796
UPC 14 Digit GTIN	00781810492796

Logistics

Minimum Pack Quantity	500
Pallet Quantity	2700
Carton Quantity	500

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)