




CL501TNMHWSS, Cu Lay-in Lug, SS Mounting Hardware Included

By Burndy
Catalog # [CL501TNMHWSS](#)

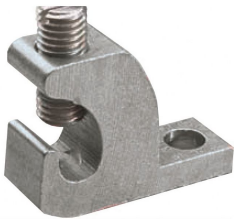

BURNDY® QIKLUG™ Copper Lay-In Lug with Stainless Steel
Tongue Mounting Hardware included

Features

- Open-faced design allows for fast lay-in of conductor without the need for cutting or breaking
- Stainless steel screws used for excellent corrosion resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor Type	CU C Str-Size
Conductor - Copper Str Size Range	14 AWG - 4 AWG
Conductor - Copper Str Size	• 14 • 13 • 12 • 11 • 10 • 9 • 8 • 7 • 6 • 5 • 4

Dimensions

Package Height	0.000 in
Dimension - Height mm	21.6 mm
Dimension - Height inch	0.85 in
Package Weight	0.000 lb.
Dimension - Width mm	10 mm
Dimension - Width inch	0.38 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	29 mm
Dimension - D inch	0.47 in
Dimension - N inch	0.19 in
Dimension - Hole Size mm	6 mm
Dimension - Hole Size inch	0.22 in
Dimension - Length Overall inch	1.13 in
Dimension - Stud Size inch	17/64

General

Plated	Y
Trade Name	QIKLUG™
Material - Hardware	Stainless Steel
UPC	781810478769
Material	Copper
Plating Type	Tin
UPC 12 Digit	781810478769
UPC 14 Digit GTIN	00781810478769

Logistics

Minimum Pack Quantity	10
Pallet Quantity	1
Carton Quantity	500

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)