




CS3CO2528250500B, Med. Voltage Cold Shrink Termination Kit, 25-28kV 3-Phase Conversion Series-Outdoor, Sleeve with Boot for Bare Concentric Conductor

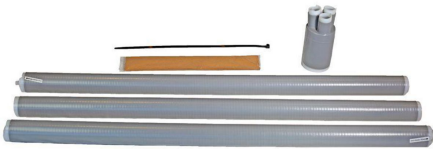

By Burndy
Catalog # [CS3CO2528250500B](#)

Medium Voltage Cold Shrink Termination Kit, 25-28kV 3-Phase Conversion Series-Outdoor, Sleeve with Boot for Bare Concentric Conductor

Features

- Rip and Grip! Does not require heat gun or any installation tools
- Spiral rip cord design provides for easy installation with effortless unwinding providing for fast removal of the hold-out core, Rip cord is recyclable
- All kits supplied with outdoor cold shrinkable tube (unprinted), 3-leg boot, seal, cable tie, and installation guide
- Quick, easy, cost effective installation utilizing one-piece terminator design
- Test reports available upon request

Application

To be used with Single Conductor, 25-28 kV XPLE and EPR non-shielded power cables for the Electrical/Industrial/Construction market.

Specifications

Buy American Compliant	Under Review
Environmental Conditions	Outdoor

Conductor

Conductor Range	• 5-8kV: 350-750 kcmil • 15kV: 250-500 kcmil
-----------------	--

- 25-28kV: #1 AWG-350 kcmil

Configuration

Boot Type	YES
-----------	-----

Current

Voltage Rating	25/28 kV
Phase	3-Phase

General

UPC	621945584969
Type	CS3CO2528-B
Material	Silicone Rubber
Series	UD-BC Series

Logistics

Carton Quantity	1
-----------------	---

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)