



CS3CO2835250500B, Medium Voltage Cold Shrink Termination Kit, 28-35kV 3-Phase Conversion Series-Outdoor, Sleeve w/ Boot for Bare Concentric Conductor

By Burndy
Catalog # [CS3CO2835250500B](#)

Medium Voltage Cold Shrink Termination Kit, 28-35kV 3-Phase Conversion Series-Outdoor, Sleeve w/ Boot for Bare Concentric Conductor

Features

- Rip and Grip! Does not require heat gun or any installation tools
- Spiral rip cord design provides for easy installation with effortless unwinding providing for fast removal of the hold-out core, Rip cord is recyclable
- All kits supplied with outdoor cold shrinkable tube (unprinted), 3-leg boot, seal, cable tie, and installation guide
- Quick, easy, cost effective installation utilizing one-piece terminator design
- Test reports available upon request

Application


To be used with Single Conductor, 28-35 kV XPLE and EPR non-shielded power cables for the Electrical/Industrial/Construction market.

Specifications

Buy American Compliant	Under Review
Environmental Conditions	Outdoor

Conductor

Conductor Range	• 5-8kV: 500-1000 kcmil • 15kV: 500-750 kcmil
-----------------	---

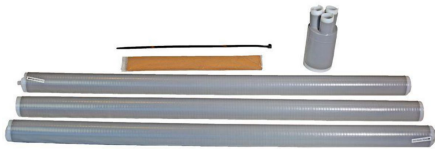

- 25-28kV: 4/0 AWG-500 kcmil
- 35kV: 1/0 AWG-350 kcmil

Configuration

Boot Type	YES
-----------	-----

Current

Voltage Rating	28/35 kV
Phase	3-Phase

General

UPC	621945584983
Type	CS3CO2835-B
Series	UD-BC Series

Logistics

Carton Quantity	1
-----------------	---

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)