




CT120200L, Cable Tie, 120 Lb Tensile, Natural

By Burndy
Catalog # [CT120200L](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength

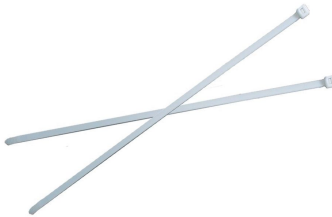

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	No
UL Listed	Yes
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in
Dimension - L Length Overall mm	221 mm
Dimension - Length Overall inch	8.70 in
Dimension - Bundle Diameter Max inch	2.00

Force Related

Installation Torque	12 LBS/in
Recommended in-lb	
Rating - Minimum Tensile Strength lbs	120

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810332924
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332924

Logistics

Minimum Pack Quantity	1000
Carton Quantity	2500
Packaging Type	Bag

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius	-40 °C
Min	

Product Assets

[Catalog \[English\]](#)



A Hubbell brand