



CT120200LO, Tie, 2" Max Bundle, 120 Lb Tensile, UV Black

By Burndy
Catalog # [CT120200LO](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength, UV Black, Nylon 6/6, 8.87" Long, 50 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For Outdoor Applications

Specifications

Buy American Compliant	Contact Manufacturer
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	Yes
Certification - CSA Approved	No
Certification - 94VO Rated	N

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	229 mm
mm	
Length	8.87 in
Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in
Dimension - Length Overall	9 in
inch	

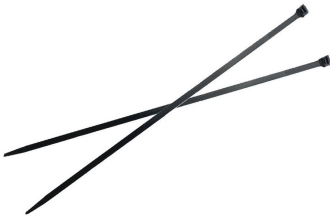

Dimension - Bundle Diameter	2.00
Max inch	

Force Related

Rating - Minimum Tensile	120
Strength lbs	

General

Trade Name	UNIRAP™
Tool Type	Standard
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810333440
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810333440

Logistics

Minimum Pack Quantity	50
Carton Quantity	2500

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius	-40 °C
Min	

Product Assets

[Catalog \[English\]](#)



A Hubbell brand