



CT120300LO, Tie, 3" Max Bundle, 120 Lb Tensile, UV Black

By Burndy
Catalog # [CT120300LO](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength, UV Black, Nylon 6/6, 11.87" Long, 50 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For Outdoor Applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	1.200 in
Package Weight	0.520 lb.
Package Length	15.750 in
Package Width	6.000 in
Dimension - L Length Overall mm	305 mm
Width	0.3 in
Length	11.87 in
Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in

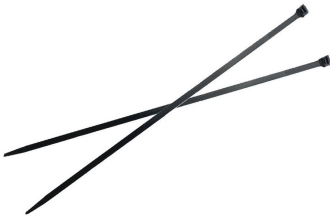

Dimension - Length Overall inch	12 in
Dimension - Bundle Diameter Max inch	3.00

Force Related

Rating - Minimum Tensile Strength lbs	120
---------------------------------------	-----

General

Trade Name	UNIRAP™
Tool Type	Standard
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810333464
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810333464

Logistics

Minimum Pack Quantity	50
Pallet Quantity	80000
Carton Quantity	2000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand