




CT120400D, Cable Tie, 120 Lb Tensile, Natural

By Burndy
Catalog # [CT120400D](#)

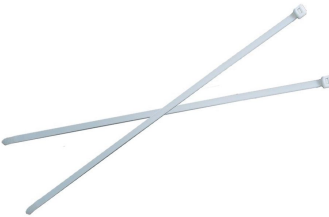

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
Industry Standard(s)	Military Specified (Mil-Spec)
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-3-9
Certification - 94V0 Rated	N

Dimensions

Dimension - Width mm	8 mm
Dimension - Width inch	0.3 in
Dimension - L Length Overall mm	383 mm
Dimension - Length Overall inch	15.09 in
Dimension - Bundle Diameter Max inch	4

Force Related

Rating - Minimum Tensile Strength lbs	120
---------------------------------------	-----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810333273
Material	Nylon 6/6
Military Specification	MS3367
UPC 14 Digit GTIN	00781810333273

Logistics

Minimum Pack Quantity	1000
Carton Quantity	2000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand