



CT120400D0, Cable Tie, 120 Lb Tensile, UV Black

By Burndy
Catalog # [CT120400D0](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For Outdoor Applications

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UV Rated	Yes
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-3-0
Certification - 94V0 Rated	N

Dimensions

Length	15.25 in
Dimension - Width mm	8 mm
Dimension - Width inch	0.3 in
Dimension - L Length Overall mm	383 mm
Width	0.3 in

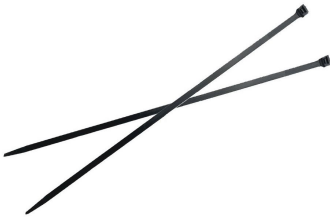

Dimension - Length Overall inch	15.09 in
Dimension - Bundle Diameter Max inch	4

Force Related

Rating - Minimum Tensile Strength lbs	120
---------------------------------------	-----

General

Color	Black
Trade Name	UNIRAP™
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810333495
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810333495

Logistics

Minimum Pack Quantity	500
Carton Quantity	2000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand