




CT120400L, Cable Tie, 4" Max Bundle, 120 Lb Tensile, Natural

By Burndy

Catalog # [CT120400L](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength

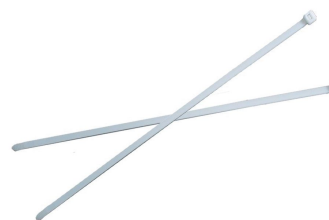

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-3-9
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	1.500 in
Package Weight	0.670 lb.
Package Length	18.750 in
Package Width	6.000 in
Dimension - L Length Overall mm	383 mm
Length	15.25 in
Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in

Dimension - Length Overall 15.09 in

Dimension - Bundle Diameter 4.00 Max inch

Force Related

Rating - Minimum Tensile Strength lbs 120

General

Trade Name	UNIRAP™
Tool Type	Standard
Military Specification	MS3367
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810333167
Type	Standard
Material	NYLON 6/6
UPC 14 Digit GTIN	00781810333167

Logistics

Pallet Quantity	48000
Carton Quantity	2000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand