



CT120400L0, Tie, 4" Max Bundle, 120 Lb Tensile, UV Black

By Burndy
Catalog # [CT120400L0](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength, UV Black 1, Nylon 6/6, 15.25" Long, 50 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For Outdoor Applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Military Spec Number	MS3367-3-0
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	1.250 in
Package Weight	0.670 lb.
Package Length	22.000 in
Package Width	6.000 in
Dimension - L Length Overall mm	383 mm
Length	15.25 in
Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in
Dimension - Length Overall inch	15.09 in

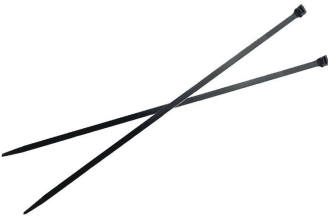

Dimension - Bundle Diameter Max 4.00 inch

Force Related

Rating - Minimum Tensile Strength 120 lbs

General

Trade Name	UNIRAP™
Tool Type	Standard
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810333488
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810333488

Logistics

Minimum Pack Quantity	50
Pallet Quantity	48000
Carton Quantity	2000

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)