



CT120400L00, Tie, 4" Max Bundle, 120 Lb Tensile, UV Black 1

By Burndy
Catalog # [CT120400L00](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength, UV Black 1,
Nylon 6/6, 15.25" Long, 50 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - cULus	Yes
Certification - UV Rated	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-3-0
Certification - 94V0 Rated	N

Dimensions

Package Height	0.000 in
Length	15.25 in
Package Weight	0.000 lb.
Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	383 mm
Width	0.3 in

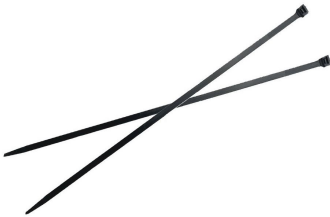

Dimension - Length Overall inch	15.09 in
Dimension - Bundle Diameter Max inch	4.00

Force Related

Rating - Minimum Tensile Strength lbs	120
---------------------------------------	-----

General

Color	UV Black (Mil. Spec.)
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810333402
Material	Nylon 6/6
Military Specification	MS3367
UPC 14 Digit GTIN	00781810333402

Logistics

Minimum Pack Quantity	50
Carton Quantity	2000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)