


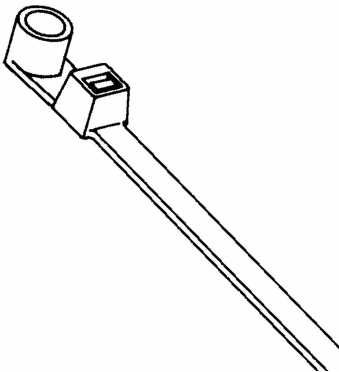

CT120400MH14D, Tie, 120 Lb Tensile, Natural, Screw Mount

By Burndy
Catalog # [CT120400MH14D](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength (Screw Mount), 50 pack

Features

- Screw Mounting Hole
- Suitable for General Use

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Configuration

Mounting Method	Screw
-----------------	-------

Dimensions

Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in
Dimension - L Length Overall mm	399 mm
Dimension - Screw Size inch	0.25
Dimension - Length Overall inch	15.70 in
Dimension - Bundle Diameter Max inch	4.00

Force Related

Rating - Minimum Tensile Strength lbs	120
---------------------------------------	-----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810335338
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810335338

Logistics

Minimum Pack Quantity	1000
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)