


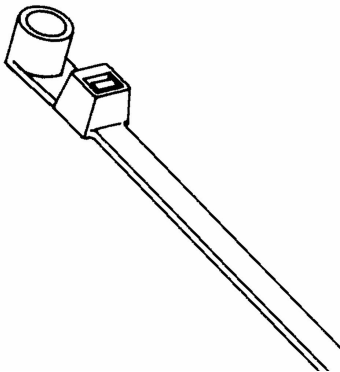

CT120400MH14L, Tie, 120 Lb Tensile, Natural, Screw Mount

By Burndy
Catalog # [CT120400MH14L](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength (Screw Mount), 50 pack

Features

- Screw Mounting Hole
- Suitable for General Use

Application

For Screw Mount

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Configuration

Mounting Method	Screw
-----------------	-------

Dimensions

Dimension - L Length Overall mm	399 mm
Dimension - Screw Size inch	1/4
Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in

Dimension - Length Overall inch	15.70 in
Dimension - Bundle Diameter Max inch	4.00

Force Related

Rating - Minimum Tensile Strength lbs	120
---------------------------------------	-----

General

Trade Name	UNIRAP™
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810335321
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810335321

Logistics

Minimum Pack Quantity	50
Carton Quantity	1000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand