




CT120800L, Cable Tie, 120 Lb Tensile, Natural

By Burndy
Catalog # [CT120800L](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength

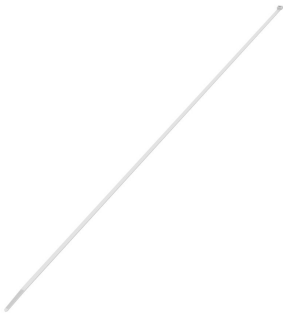

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For general purpose applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	742 mm
mm	
Dimension - Thread Size	-
Dimension - Width mm	8 mm
Dimension - Width inch	0.30 in
Dimension - Length Overall	29.2 in
inch	
Dimension - Bundle Diameter	8.00
Max inch	

Force Related

Rating - Minimum Tensile	120
Strength N	
Rating - Minimum Tensile	120
Strength lbs	

General

Trade Name	UNIRAP
Tool Type	Standard
Color	Natural
Color Code	Natural
Sub Brand	UNIRAP
Series	UNIRAP™ Series
UPC	781810661079
Type	CT-L
Material	Nylon 6/6
UPC 12 Digit	781810661079
UPC 14 Digit GTIN	00781810661079

Logistics

Minimum Pack Quantity	50
Pallet Quantity	1
Carton Quantity	500

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius	-40 °C
Min	

Product Assets

[Catalog \[English\]](#)



A Hubbell brand