



CT120800L00, Cable Tie, 120 Lb Tensile, Black

By Burndy
Catalog # [CT120800L00](#)

Nylon UNIRAP™ Cable Tie - 120 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For connecting cable to ground rod

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	1.000 in
Package Weight	1.440 lb.
Dimension - Width mm	7.6 mm
Dimension - Width inch	0.30 in
Package Length	40.000 in
Package Width	7.800 in
Dimension - L Length Overall mm	724 mm
Dimension - Length Overall inch	28.51 in

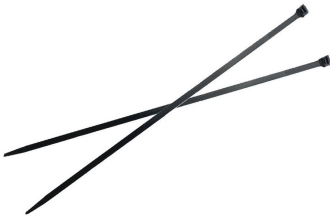

Dimension - Bundle Diameter	8.00
Max inch	

Force Related

Rating - Minimum Tensile	120
Strength lbs	

General

Color	UV Black (Mil. Spec.)
Trade Name	UNIRAP™
Sub Brand	UNIRAP
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810661086
Type	STANDARD
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810661086

Logistics

Minimum Pack Quantity	50
Pallet Quantity	21000
Carton Quantity	500

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius	-40 °C
Min	

Product Assets

[Catalog \[English\]](#)