




CT1751100Q, Tie, 11" Max Bundle, 175 Lb Tensile, Natural

By Burndy
Catalog # [CT1751100Q](#)

Nylon UNIRAP™ Cable Tie - 175 Lb. Tensile Strength, Natural, Nylon 6/6, 36.5" Long, 25 pack

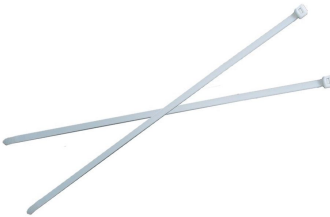

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-13-9
Certification - 94V0 Rated	N

Dimensions

Package Height	1.000 in
Length	36.5 in
Package Weight	1.060 lb.
Dimension - Width mm	8.6 mm
Dimension - Width inch	0.34 in
Package Length	42.000 in
Package Width	6.000 in
Dimension - L Length Overall mm	927 mm
Width	0.34 in
Dimension - Length Overall inch	36.50 in

Dimension - Bundle Diameter Max inch	11.00
--------------------------------------	-------

Force Related

Rating - Minimum Tensile Strength lbs	175
---------------------------------------	-----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Heavy
UPC	781810333853
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810333853

Logistics

Minimum Pack Quantity	25
Pallet Quantity	15000
Carton Quantity	500
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	0 °C

Product Assets

[Catalog \[English\]](#)