




CT1751100Q0, Tie, 11" Max Bundle, 175 Lb Tensile, UV Black

By Burndy
Catalog # [CT1751100Q0](#)

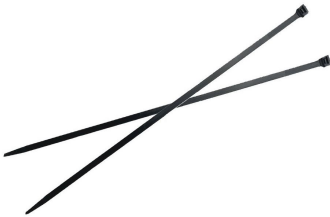

Nylon UNIRAP™ Cable Tie - 175 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For Outdoor Applications

Specifications

Certification - UL Recognized	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Military Spec Number	MS3367-13-0
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	927 mm
mm	
Width	0.35 in
Length	36 in
Dimension - Width mm	8.6 mm
Dimension - Width inch	0.34 in

Dimension - Length Overall	36.50 in
inch	
Dimension - Bundle Diameter	11.00
Max inch	

Force Related

Rating - Minimum Tensile	175
Strength lbs	

General

Trade Name	UNIRAP™
Tool Type	Heavy
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810334133
Type	Heavy
Material	NYLON 6/6
UPC 14 Digit GTIN	00781810334133

Logistics

Carton Quantity	500
-----------------	-----

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius	0 °C
Min	

Product Assets

[Catalog \[English\]](#)



A Hubbell brand