



CT1751100Q0UG, Tie, 11" Max Bundle, 175 Lb Tensile, UV Black

By Burndy
Catalog # [CT1751100Q0UG](#)

Nylon UNIRAP™ Cable Tie - 175 Lb. Tensile Strength (Universal Grade), 25 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
Length	36 in
Package Weight	0.000 lb.
Dimension - Width mm	8.9 mm
Dimension - Width inch	0.35 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	914 mm
Width	0.35 in

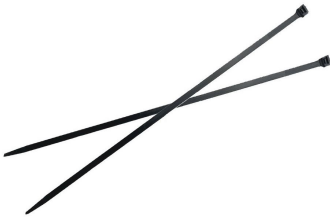

Dimension - Length Overall inch	36.00 in
Dimension - Bundle Diameter Max inch	11.00

Force Related

Rating - Minimum Tensile Strength lbs	175
---------------------------------------	-----

General

Color	UV Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Heavy
UPC	781810499177
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810499177

Logistics

Minimum Pack Quantity	25
Pallet Quantity	15000
Carton Quantity	500

Product Assets

[Catalog \[English\]](#)