



CT1751100QUG, Tie, 11" Max Bundle, UV Black, Universal Grade

By Burndy
Catalog # [CT1751100QUG](#)

Nylon UNIRAP™ Cable Tie - 175 Lb. Tensile Strength (Universal Grade), 25 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.345 in
Length	36 in
Package Weight	0.907 lb.
Dimension - Width mm	8.9 mm
Dimension - Width inch	0.35 in
Package Length	40.750 in
Package Width	6.300 in
Dimension - L Length Overall mm	914 mm
Width	0.35 in

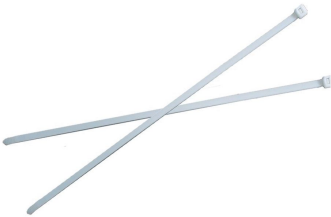

Dimension - Length Overall inch	36.00 in
Dimension - Bundle Diameter Max inch	11.00

Force Related

Rating - Minimum Tensile Strength lbs	175
---------------------------------------	-----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Heavy
UPC	781810486061
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810486061

Logistics

Minimum Pack Quantity	25
Pallet Quantity	18000
Carton Quantity	500

Product Assets

[Catalog \[English\]](#)