




CT175600Q, Cable Tie, 6" Max Bundle, 175 Lb Tensile, Natural

By Burndy
Catalog # [CT175600Q](#)

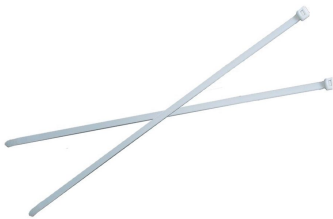

Nylon UNIRAP™ Cable Tie - 175 Lb. Tensile Strength, Natural, Nylon 6/6, 21" Long, 25 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	Yes
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-10-9
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94VO Rated	N

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	622 mm
Width	0.35 in
Length	21 in

Dimension - Width mm	8.9 mm
Dimension - Width inch	0.35 in
Dimension - Length Overall inch	24.51 in
Dimension - Bundle Diameter Max inch	7.00

Force Related

Rating - Minimum Tensile Strength lbs	175
---------------------------------------	-----

General

Trade Name	UNIRAP™
Tool Type	Heavy
Military Specification	MS3367
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810333631
Type	Heavy
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810333631

Logistics

Minimum Pack Quantity	25
Carton Quantity	500

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	0 °C

Product Assets

[Catalog \[English\]](#)