



CT175600Q0UG, Tie, 6" Max Bundle, UV Black, Universal Grade

By Burndy
Catalog # [CT175600Q0UG](#)

Nylon UNIRAP™ Cable Tie - 175 Lb. Tensile Strength (Universal Grade), 25 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For both field and production line use

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	1.000 in
Length	21 in
Package Weight	0.580 lb.
Dimension - Width mm	8.9 mm
Dimension - Width inch	0.35 in
Package Length	29.250 in
Package Width	5.400 in

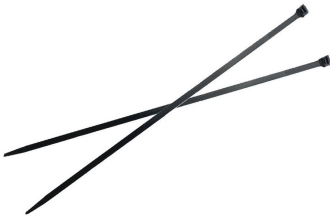

Dimension - L Length Overall mm	610 mm
Width	0.35 in
Dimension - Length Overall inch	24.00 in
Dimension - Bundle Diameter Max inch	6.00

Force Related

Rating - Minimum Tensile Strength lbs	175
---------------------------------------	-----

General

Color	UV Black
Trade Name	UNIRAP™
Sub Brand	CABLE TIE
Series	UNIRAP™ Series
Tool Type	Heavy
UPC	781810499160
Type	CT_UG
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810499160

Logistics

Minimum Pack Quantity	25
Pallet Quantity	30000
Carton Quantity	1500

Product Assets

[Catalog \[English\]](#)