



CT18075C00, Tie, .75" Max Bundle, 18 Lb Tensile, UV Black

By Burndy
Catalog # [CT18075C00](#)

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength, UV Black, Nylon 6/6, 4.10" Long, 100 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-4-0
Certification - 94V0 Rated	N

Dimensions

Package Height	0.800 in
Length	4.1 in
Package Weight	0.070 lb.
Dimension - Width mm	2.5 mm
Dimension - Width inch	0.10 in
Package Length	8.000 in
Package Width	3.800 in
Dimension - L Length Overall mm	104 mm
Width	0.1 in
Dimension - Length Overall inch	4.10 in

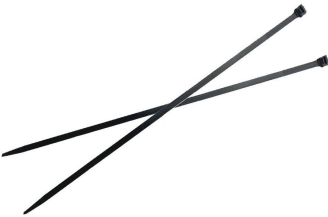

Dimension - Bundle Diameter Max inch	0.75
--------------------------------------	------

Force Related

Rating - Minimum Tensile Strength lbs	18
---------------------------------------	----

General

Color	UV Black (Mil. Spec.)
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Mini
UPC	781810331682
Material	Nylon 6/6
Military Specification	MS3367
UPC 14 Digit GTIN	00781810331682

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)