




CT18075FLC, Tie, .75" Max Bundle, Natural, Identification

By Burndy
Catalog # [CT18075FLC](#)

Nylon UNIRAP - 18 Lb. Tensile Strength (ID Flag)

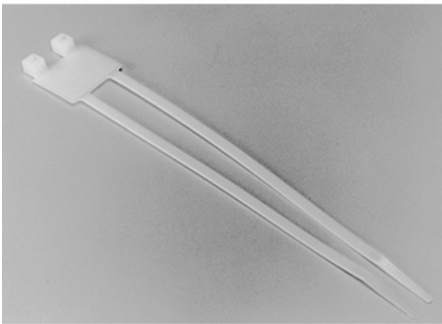

Features

- Identification

Specifications

Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.800 in
Length	4.1 in
Package Weight	0.110 lb.
Dimension - Width mm	2.5 mm
Dimension - Width inch	0.10 in
Package Length	9.600 in
Package Width	4.900 in
Dimension - L Length Overall mm	104 mm
Dimension - Marking Pad Size inch	0.36 X 0.81
Width	0.1 in
Dimension - Length Overall inch	4.10 in

Dimension - Bundle Diameter Max 0.75 inch

Force Related

Rating - Minimum Tensile Strength 18 lb lbs

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810335376
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810335376

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	20000

Product Assets

[Catalog \[English\]](#)