




CT18075M0, Tie, .75" Max Bundle, 18 Lb Tensile, UV Black

By Burndy
Catalog # [CT18075M0](#)

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength

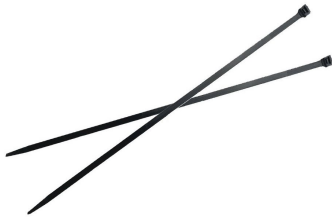

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-4-0
Certification - 94V0 Rated	N

Dimensions

Package Height	2.600 in
Length	4.1 in
Package Weight	0.630 lb.
Dimension - Width mm	2.5 mm
Dimension - Width inch	0.1 in
Package Length	9.500 in
Package Width	5.100 in
Dimension - L Length Overall mm	104 mm
Width	0.1 in

Dimension - Length Overall inch	4.1 in
Dimension - Bundle Diameter Max inch	0.75

Force Related

Rating - Minimum Tensile Strength lbs	18
---------------------------------------	----

General

Color	Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810331750
Material	Nylon 6/6
Military Specification	MS3367
UPC 14 Digit GTIN	00781810331750

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	10000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand