



CT18075MH4M, Tie, .75" Max Bundle, Natural, Screw Mount

By Burndy
Catalog # [CT18075MH4M](#)

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength (Screw Mount), 1000 pack

Features

- Mounting Hole

Specifications


Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	Yes
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Configuration

Mounting Method	Screw
-----------------	-------

Dimensions

Package Height	0.000 in
Length	3.93 in
Package Weight	0.000 lb.
Dimension - Width mm	3 mm
Dimension - Width inch	0.10 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	100 mm
Width	0.1 in
Dimension - Screw Size inch	#4
Dimension - Length Overall inch	3.93 in

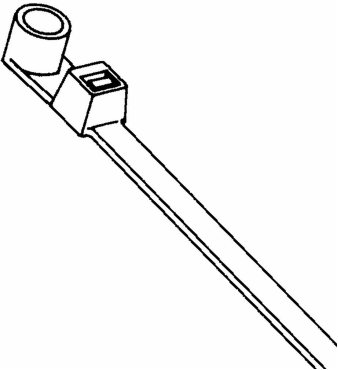

Dimension - Bundle Diameter Max inch	0.75
--------------------------------------	------

Force Related

Rating - Minimum Tensile Strength lbs	18
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810335178
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810335178

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	1
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)