



CT18125C3, Tie, 1.25" Max Bundle, 18 Lb Tensile, Orange

By Burndy
Catalog # [CT18125C3](#)

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength, Orange, Nylon 6/6, 6.18" Long, 100 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Length	6.18 in
Dimension - Width mm	2 mm
Dimension - Width inch	0.09 in
Dimension - L Length Overall mm	157 mm
Width	0.09 in
Dimension - Length Overall inch	6.18 in
Dimension - Bundle Diameter Max inch	1.50 in

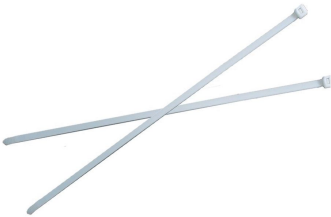

Force Related

Rating - Minimum Tensile Strength lbs	18
---------------------------------------	----

General

Color	Orange
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Mini
UPC	781810331477
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810331477

Logistics

Minimum Pack Quantity	100
Pallet Quantity	1
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)