




CT18125M0, Tie, 1.25" Max Bundle, 18 Lb Tensile, UV Black

By Burndy
Catalog # [CT18125M0](#)

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength

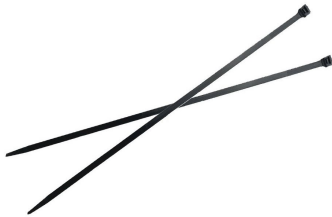

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	1.500 in
Length	6.18 in
Package Weight	0.910 lb.
Dimension - Width mm	2 mm
Dimension - Width inch	0.09 in
Package Length	13.500 in
Package Width	9.000 in
Dimension - L Length Overall mm	157 mm
Width	0.09 in
Dimension - Length Overall inch	6.18 in

Dimension - Bundle Diameter Max inch	1.50 in
--------------------------------------	---------

Force Related

Rating - Minimum Tensile Strength lbs	18
---------------------------------------	----

General

Color	Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810331774
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810331774

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	10000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand