


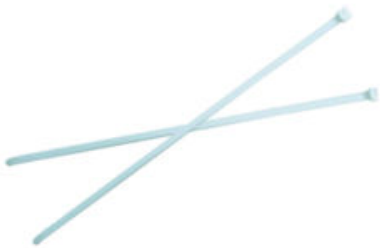

CT18200C2, Cable Tie, 2" Max Bundle, 18 Lb Tensile, Red

By Burndy
Catalog # CT18200C2

Nylon cable ties, Tensile strength-18 Lbs, Color- Red, 8.18"L, 0.09"W, 2.10" Bundle Dia.



Features

Standard Cable Tie

General

Color	Red
Material	NYLON 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	18
Tool Type	Mini
Trade Name	UNIRAP™
UPC	781810331583

Dimensions

Dimension - Bundle Diameter Max inch	2.10 in
Dimension - L Length Overall mm	208 mm
Dimension - Length Overall inch	8.18 in
Dimension - Width inch	0.09 in
Dimension - Width mm	2 mm

Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	1000
Minimum Pack Quantity	100
Packaging Type	Bag

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
[Sales Drawings - 50080813](#)



A proud member of the Hubbell Family.