


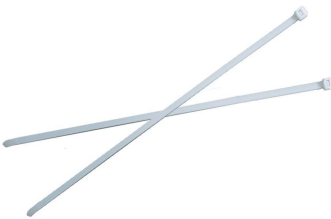

CT18200C6, Cable Tie, 2" Max Bundle, 18 Lb Tensile, Blue

By Burndy
Catalog # [CT18200C6](#)

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength, Blue, Nylon 6/6, 8.18" Long, 100 pack



Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.000 in
Length	8.18 in
Package Weight	0.000 lb.
Dimension - Width mm	2 mm
Dimension - Width inch	0.09 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	208 mm
Width	0.09 in
Dimension - Length Overall inch	8.18 in

Dimension - Bundle Diameter Max inch	2.10 in
--------------------------------------	---------

Force Related

Rating - Minimum Tensile Strength lbs	18
---------------------------------------	----

General

Color	Blue
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Mini
UPC	781810331620
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810331620

Logistics

Minimum Pack Quantity	100
Pallet Quantity	1
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)