


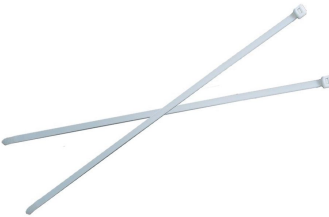

CT18200M, Cable Tie, 2" Max Bundle, 18 Lb Tensile, Natural

By Burndy
Catalog # [CT18200M](#)

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength, Natural, Nylon 6/6, 8" Long, 1000 pack



Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	2.800 in
Package Weight	1.170 lb.
Package Length	12.500 in
Package Width	7.000 in
Dimension - L Length Overall	208 mm
mm	
Length	8 in
Dimension - Width mm	2 mm
Dimension - Width inch	0.09 in

Dimension - Length Overall	8.18 in
inch	
Dimension - Bundle Diameter	2.10 in
Max inch	

Force Related

Rating - Minimum Tensile	18
Strength lbs	

General

Trade Name	UNIRAP™
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810331675
Type	Mini
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810331675

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	10000

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius	-40 °C
Min	

Product Assets

[Catalog \[English\]](#)