




CT18200M0, Cable Tie, 18 Lb Tensile, UV Black

By Burndy

Catalog # [CT18200M0](#)

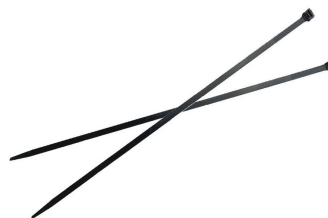

Nylon UNIRAP™ Cable Tie - 18 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For Outdoor Applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	2.800 in
Package Weight	1.170 lb.
Package Length	12.500 in
Package Width	7.000 in
Dimension - L Length Overall mm	208 mm
Dimension - Width mm	2 mm
Dimension - Width inch	0.09 in

Dimension - Length Overall 8.18 in

Dimension - Bundle Diameter 2.10 in

Force Related

Rating - Minimum Tensile Strength lbs 18

General

Trade Name	UNIRAP™
Color	Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810331798
Type	Mini
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810331798

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	10000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand