




CT2501000RQ, Cable Tie, 10" Max Bundle, Natural, Releasable

By Burndy

Catalog # [CT2501000RQ](#)

Nylon UNIRAP™ Cable Tie - 250 Lb. Tensile Strength (Releasable), 25 pack

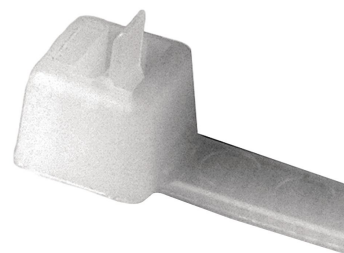

Features

- Releasable Cable Tie
- Specially suitable for prototype construction or temporary installation
- Also suitable where service often requires adding or subtracting wires from an existing bundle

Specifications

Standards - RoHS Compliance CM

Status

Certification - UV Rated No

Certification - CSA Approved No

Certification - 94V0 Rated N

Dimensions

Package Height 1.250 in

Length 34 in

Package Weight 1.360 lb.

Dimension - Width mm 13 mm

Dimension - Width inch 0.50 in

Package Length 37.500 in

Package Width 8.000 in

Dimension - L Length Overall mm 864 mm

Width 0.5 in

Dimension - Length Overall inch 34.00 in

Dimension - Bundle Diameter 10.00 Max inch

Force Related

Rating - Minimum Tensile Strength lbs 250

General

Color Natural

Trade Name UNIRAP™

Series UNIRAP™ Series

UPC 781810334881

Material Nylon 6/6

UPC 14 Digit GTIN 00781810334881

Logistics

Minimum Pack Quantity 1000

Pallet Quantity 925

Carton Quantity 1000

Packaging Type Bag

Operational

Operating Temperature Celcius 85 °C Max

Operating Temperature Celcius -40 °C Min

Product Assets

[Catalog \[English\]](#)



A Hubbell brand