



CT250200RQ0, Tie, 2.25" Max Bundle, UV Black, Releasable

By Burndy
Catalog # [CT250200RQ0](#)

Nylon UNIRAP™ Cable Tie - 250 Lb. Tensile Strength (Releasable), 25 pack

Features


- Releasable Cable Tie
- Specially suitable for prototype construction or temporary installation
- Also suitable where service often requires adding or subtracting wires from an existing bundle

Specifications

Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	Yes
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.000 in
Length	9 in
Package Weight	0.000 lb.
Dimension - Width mm	13 mm
Dimension - Width inch	0.50 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	229 mm
Width	0.5 in
Dimension - Length Overall inch	9 in
Dimension - Bundle Diameter Max inch	2.25

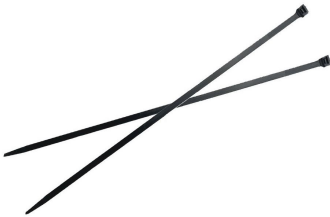

Force Related

Rating - Minimum Tensile Strength lbs	250
---------------------------------------	-----

General

Color	Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810334812
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810334812

Logistics

Minimum Pack Quantity	1500
Pallet Quantity	1
Carton Quantity	1500
Packaging Type	Bag

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius	-40 °C
Min	

Product Assets

[Catalog \[English\]](#)



A Hubbell brand